




EIF2A Antibody

CATALOG NUMBER: 49-234

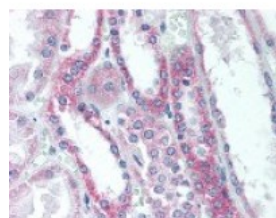

Immunohistochemistry staining of EIF2A in kidney (formalin-fixed paraffin-embedded) tissue using EIF2A Antibody.

Specifications

SPECIES REACTIVITY:	Human, Mouse
TESTED APPLICATIONS:	IHC, WB
APPLICATIONS:	ELISA, immunofluorescence. EIF2A antibody can be used in ELISA starting at 1: 10000, Western Blot starting at 1: 500 - 1: 2000, immunohistochemistry starting at 1:200, and immunofluorescence starting at 1:200 - 1:1000.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	EIF2A antibody was raised against recombinant (partial), C-Terminal region of EIF2A (Mouse).
HOST SPECIES:	Rabbit

Properties

PURIFICATION:	Immunoaffinity Chromatography
PHYSICAL STATE:	Liquid
BUFFER:	Phosphate-buffered solution, pH 7.2, 0.09% sodium azide, 50% glycerol.
STORAGE CONDITIONS:	Aliquot and store EIF2A antibody at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Polyclonal
ISOTYPE:	IgG
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	EIF2S1, EIF-2-alpha, EIF-2alpha, EIF2 alpha, EIF2, EIF-2, EIF-2A
ACCESSION NO.:	P05198
PROTEIN GI NO.:	124200
OFFICIAL SYMBOL:	EIF2S1
GENE ID:	1965

Background

